


Product data sheet

Characteristics

NSYEC361

Spacial SF 1 entry cable gland plate - fixed by clips - 300x600 mm

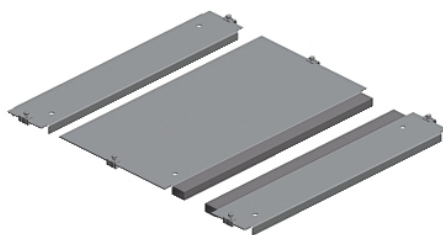

Main

Range	Spacial
Product or component type	Cable gland plate
Accessory / separate part category	Cable management accessory
Application	Prisma application Multi-purpose
Range compatibility	Spacial Spacial SF Spacial Spacial SFM
Mounting location	Enclosure bottom
Cable gland type	Standard
Cable entry	1 entry
Device composition	Fixing elements 1 plate Self extinguishing polyurethane adhesive gasket with cross-section of 15 x 25 mm
Quantity per set	Set of 1
Material	Galvanised steel

Complementary

Height	20 mm
Width	300 Mm nominal: 116 Mm useful: 144 mm real:
Depth	600 mm nominal:
Thickness	1.5 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3 cm
Package 1 Width	13 cm
Package 1 Length	45.5 cm
Package 1 Weight	1.342 kg
Unit Type of Package 2	PAL
Number of Units in Package 2	20
Package 2 Height	29 cm
Package 2 Width	45 cm
Package 2 Length	120 cm
Package 2 Weight	26.84 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Logistical informations

Country of origin	FR
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------