


Product data sheet

Characteristics

NSYSPS3200

Spacial SM side panel plinth - 200x300 mm

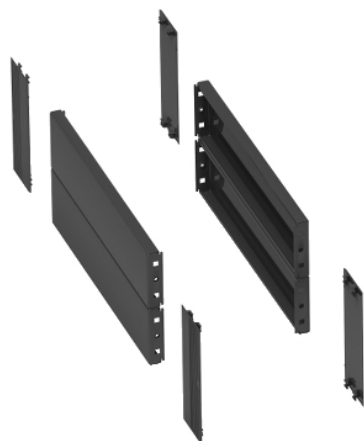

Main

Range	Spacial
Accessory / separate part category	Enclosure accessory
Product or component type	Plinth side panel
Application	Multi-purpose
Nominal dimensions of the housing	-
Device composition	Fixing elements 4 corner cover 2 side panel
Range compatibility	Spacial Spacial SM
Mounting support	Front plinth

Complementary

Fixing mode	By screws
Colour	Grey (RAL 7022)
Surface finish	Epoxy-polyester powder
Height	200 mm
Width	300 mm nominal:

Environment

IP degree of protection	IP20 (complete plinth)
IK degree of protection	IK10

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.500 cm
Package 1 Width	11.500 cm
Package 1 Length	30.500 cm
Package 1 Weight	1.389 kg
Unit Type of Package 2	S03
Number of Units in Package 2	7
Package 2 Height	30 cm
Package 2 Width	30 cm
Package 2 Length	40 cm
Package 2 Weight	10.143 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 mois
----------	---------