

Product data sheet


Characteristics

NSYCRS200W240V

Climasys Ultra thin resistance heater low starting current 195W 240V 400x650mm



Local distributor code: 400815756
EAN Code: 3606480530203

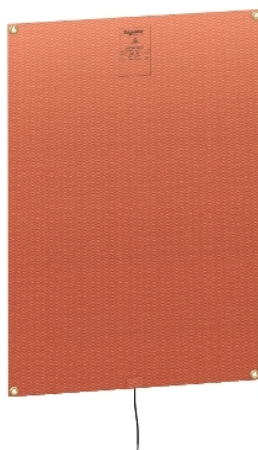

Main

Range	ClimaSys
Product name	ClimaSys CR
Product or component type	Ultra thin resistance heater
Power range	195 W
Input voltage	240 V AC 50/60 Hz
Electrical connection	Cable length: 2 m

Complementary

Operating position	Horizontal Vertical
Ambient air temperature for operation	-60...70 °C
Temperature setting range	-40...70 °C
Material	Silicone rubber
Height	380 mm external:
Width	650 mm external:
Depth	1.6 mm external:
Device composition	6 self-adhesive Velcro pads 6 plastic spacers 4 Telequick nuts 4 clip-on nuts Fixing accessories
Condition of use	Air sealed enclosure Heaters must be installed with a thermal controller Electrical protection is needed
Fixing mode	By 4 screws
Mounting support	Adhesive Velcro Telequick mounting plate Standard mounting plate DIN rail

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.5 cm
Package 1 Width	43.0 cm
Package 1 Length	69.5 cm
Package 1 Weight	1.13 kg
Unit Type of Package 2	P12
Number of Units in Package 2	30
Package 2 Height	150.0 cm

Package 2 Width	80.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	47.0 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile
Circularity Profile	No need of specific recycling operations
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

Logistical informations

Country of origin	ES
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------