


Product data sheet

Characteristics

XZCC51FCP50B

female, type 717, 5-pin, elbowed connector - cable gland Pg 11

Important message: We have updated the process for ordering Telemecanique Sensors products. For more information, please contact your Telemecanique Sensors representative in the UK&I at: UK.salesorders@tesensors.com. You can find all product information on the Telemecanique Sensors website: www.tesensors.com/uk/en
EAN Code: 3389110833966

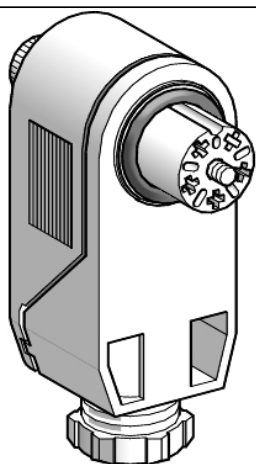

Main

Range of product	Telemecanique Cabling components
Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Elbowed female connector type 717, 5 pins
Status LED	Without
Cable connection	Screw terminal / wire size <1.5 mm ² / clamping capacity 7...10 mm

Complementary

Cable gland type	Pg 11
Cable connector fixing	Locking screw
[Ue] rated operational voltage	250 V AC 300 V DC
[In] rated current	16 A
Enclosure material	Plastic
Minimum insulating resistance	10 GΩ
Contact resistance	5000 μOhm

Environment

IP degree of protection	IP67
Ambient air temperature for operation	-25...90 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1

Contractual warranty

Warranty	18 months
----------	-----------