


Product data sheet

Characteristics

ZC1AC008

Limit switch head, Limit switches XC Standard, ZC1AC, offset roller lever

Important message: We have updated the process for ordering Telemecanique Sensors products. For more information, please contact your Telemecanique Sensors representative in the UK&I at: UK.salesorders@tesensors.com. You can find all product information on the Telemecanique Sensors website: www.tesensors.com/uk/en
EAN Code: 3389110322644

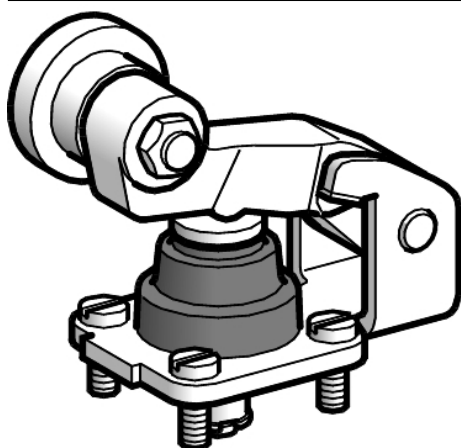

Main

Range of product	OsiSense XC
Series name	Special format
Product or component type	Limit switch head
Device short name	ZC1AC
Head type	Plunger head
Product compatibility	XC1AC
Movement of operating head	Linear
Type of operator	Spring return roller lever metal offset
Switch actuation	By 30° cam
Type of approach	Lateral approach, 2 directions
Positive opening	Without

Complementary

Net weight	0.1 kg
------------	--------


Environment

Ambient air temperature for operation	-25...70 °C
Ambient air temperature for storage	-40...70 °C
Environmental characteristic	Standard environment

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3 cm
Package 1 Width	3 cm
Package 1 Length	7 cm
Package 1 Weight	102 g

Offer Sustainability

REACH Regulation	 REACH Declaration
EU RoHS Directive	Not applicable, out of EU RoHS legal scope

Contractual warranty

Warranty	18 months
----------	-----------