


Product data sheet

Characteristics

XGSZ22E4503

Jumper Ethernet M12/RJ45 straight/elbowed shielded 3m

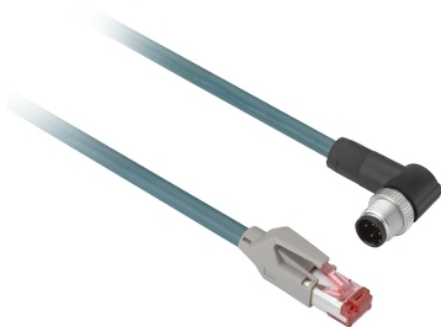

Main

Range of product	OsiSense XG
Accessory / separate part category	Connection accessories
Accessory / separate part type	Connecting cable
Product or component type	Ethernet copper cable
Product compatibility	XGSZ33ETH XGSZ33EIP XUW
Accessory / separate part destination	Ethernet network

Complementary

Cable length	3 m
Transmission rate	100 Mbit/s
Transmission support medium	2 twisted shielded pairs
Communication network category	5e
AWG gauge	AWG 26
Electrical connection	1 male connector, RJ45 straight connector with 4 pin(s) 1 male connector, M12 elbowed connector with 4 pin(s) - encoding type: D coding
Conductor material	Copper
Cover material	PUR

Environment

IP degree of protection	IP67
Standards	IEC 60754-1 EIA/TIA-568 ISO/IEC 11801 Ed.2, 2002
Environmental characteristic	RoHS compliant

Offer Sustainability

EU RoHS Directive	Not applicable, out of EU RoHS legal scope
-------------------	--

Contractual warranty

Warranty	18 months
----------	-----------

Wiring Diagram

