

Product data sheet

Characteristics

XALK02

Harmony XALD, XALK, 빈 제어 스테이션, 플라스틱, 노란색, 1 컷아웃, 표시가 되지 않은 UL/CSA 인증



기본항목

제품의 범위	하모니 XALK
제품 또는 구성요소 타입	비어 있는 제어 스테이션
모델명	XALK
제품 도착점	XB5 Ø 22 mm 제어 및 시그널링 장치용
제어 스테이션 응용프로그램	긴급 전환 off 기능 긴급 멈춤 기능
컷아웃의 수	컷아웃 2개
인클로저의 베이스의 색상	조명 회색 RAL 7035)
커버의 색상	노란색 RAL 1021)
자재	폴리카보네이트
케이블 입구	케이블 입구용 녹아웃 2개, 클램프 정전용량: 14 mm Pg 13 케이블 글랜드 및 ISO M20용 녹아웃 2개, 클램프 정전용량: 12 mm
IP 등급	IP66 일치되는 IEC 60529 IP67 IP69 IP69K

전기적/기계적 특성

어셈블리 스타일	고객 어셈블리용
수평 열의 수	1
수직 열의 수	2
제품 무게	0.193 kg
높이 압력 와셔에 대한 저항	7000000 Pa 에서 55 °C, 거리: 0.1 m
블록의 마운팅	전면 마운팅 Rear mounting
주요 그룹	2 cut-outs
제품 그룹	표준 노란색

사용환경

보호 처리	TH
저장온도	-40...70 °C
사용온도	-40...70 °C
과전압 카테고리	Class II 일치되는 IEC 60536
보호의 NEMA 정도	NEMA 13 NEMA 4X
보호의 IK 정도	IK03 conforming to IEC 62262
표준	IEC 60947-5-5 UL 508 IEC 60947-1 IEC 60947-5-4 CSA C22.2 No 14 JIS C8201-5-1 IEC 60947-5-1 JIS C8201-1

포장 단위

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.0 cm
Package 1 Width	8.0 cm
Package 1 Length	10.7 cm
Package 1 Weight	187.0 g
Unit Type of Package 2	S03
Number of Units in Package 2	36
Package 2 Height	30.0 cm
Package 2 Width	30.0 cm
Package 2 Length	40.0 cm
Package 2 Weight	7.134 kg


상품의 지속 가능성

지속 가능성 제공 상태	Green Premium 제품
REACH 규정	 REACH 선언
SVHC 없는 REACH	예
EU RoHS 지침	선제 준수(EU RoHS 법적 범위 외 제품)  EU RoHS 선언
유독성 중금속 없음	예
수은 없음	예
중국 RoHS 규정	 중국 RoHS 선언
RoHS 면제 정보	 예
환경 공시	 제품 환경 프로파일
순환성 프로파일	 수명 종료 정보

계약 보증

보증	18 개월
----	-------

Dimensions

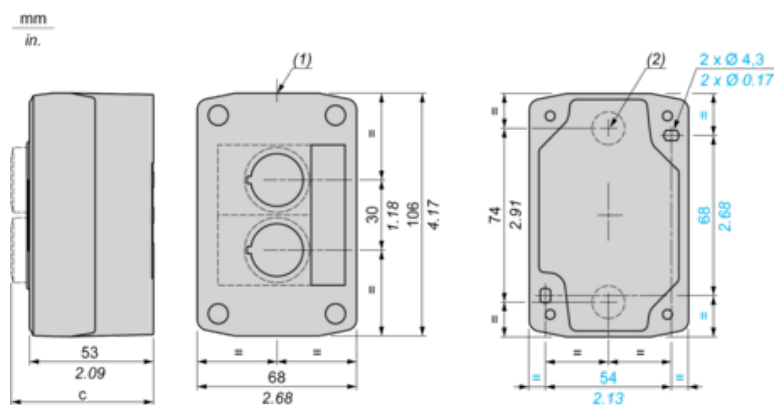

(1) 2 knock-outs for Pg 13.5 cable gland, maximum capacity 12 mm/0.47 in.

(2) Knock-out for cable entry, maximum capacity 14 mm/0.55 in.

Control station fitted with:	c in mm	c in in.
Flush pushbutton	62	2.44
Pilot light	64	2.52
Illuminated pushbutton	65.5	2.58
Projecting pushbutton	66	2.60
Selector switch	80	3.15
Mushroom head pushbutton	91.5	3.58
Latching mushroom head Emergency stop pushbutton with key	115	4.53
Key switch	105.5	4.15