


Product data sheet

Characteristics

21115

current limiting block - 63 A - for P25M

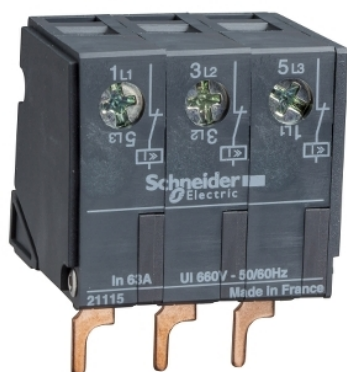

Principal

Aplicatie disjunctor	Circuit comandă
Gama de produse	P25M
Nume scurt al dispozitivului	Limiter block
Descriere poli	3P

Suplimentar

[In] curent nominal	63 A
Capacitate de rupere	100 kA at 415 V AC
Mod de montare	Fixed downside Fixed upside
Suport de montare	Conectare
Pasi de 9 mm	5
Conexiuni - borne	Tunnel type terminals 25 mm ² flexibile

Mediu

Standarde	IEC 947-2 IEC 947-4
Certificari produs	NEMKO CEBEC SEMKO DEMKO

Offer Sustainability

Directiva RoHS UE	Conform Declaratia RoHS UE
Fara metale grele toxice	Da
Fara mercur	Da
Informatii privind scutirea de la RoHS	Da
Regulamentul RoHS China	Declaratia RoHS China
WEEE	În Uniunea Europeana, produsele trebuie reciclate respectand sistemul specific de colectare a deeurilor si nu trebuie sa ajunga in pubelele de colectare a deeurilor menajere.