


Product data sheet

Characteristics

ALB45739

Altira - Rama De Acoperire - 3 Porti Verticale - Gri Ceata - 71 Mm

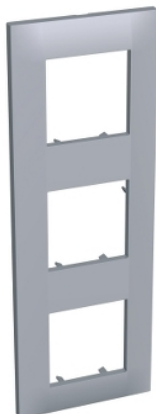

Principal

Gama	Altira
Nume rama decorativa	Culoare
Tip produs sau componenta	Rama decorativa
Tenta de culoare cadru capac	Gri cețos

Suplimentar

Numar de module	6 module
Numar de porti	3 porti vertical
Mod de fixare	Presiune fixata la 4 puncte
Tratament de suprafata	Netratat
Finisaj suprafata	Satin
Adancime	13,5 mm
Distanta intre centre	71 mm
Greutate neta	0,035 kg

Mediu

Caracteristica de mediu	Benzină Fluid de curățare a geamurilor Alcool Hidrogen peroxid (H2O2) Ulei Săpun lichid Rezistent UV Decolorant Acetonă
-------------------------	---

Unitati de ambalare

Tip unitate a formei de impachetare 1	PCE
Număr de produse în pachet	1
Greutate colet(Lbs)	35,0 g
Inaltimea formei de impachetare 1	22,5 cm
Latimea formei de impachetare 1	8 cm
Lungimea formei de impachetare 1	1,3 cm
Tip unitate a formei de impachetare 2	S03
Numar de unitati in forma de impachetare 2	20
Greutatea formei de impachetare 2	1,692 kg
Inaltimea formei de impachetare 2	30 cm
Latimea formei de impachetare 2	30 cm
Lungimea formei de impachetare 2	40 cm
Tip unitate a formei de impachetare 3	BB1

Numar de unitati in forma de impachetare 3	5
Greutatea formei de impachetare 3	292,0 g
Inaltimea formei de impachetare 3	7,8 cm
Latimea formei de impachetare 3	14,3 cm
Lungimea formei de impachetare 3	30 cm

Garantie contractuala

Garantie	18 luni
----------	---------