


Product data sheet

Characteristics

RUW241P7

Circuit Rc, 110, 240 V Ac, pentru Prize Rpz/
Ruz

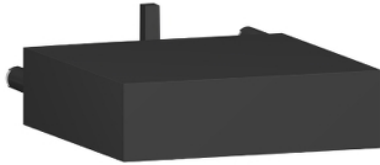

Principal

Gama de produse	Harmony Electromechanical Relays
Categorii accesorii / piese de schimb	Accesorii de protectie
Tip produs sau componenta	Protection module
Denumire accesorii/ piese separate	Circuit RC
Compatibilitate produs	Soclu RPZ (3 C/O)[RETURN]Soclu RPZ (4 C/O) [RETURN]Soclu RUZ (2 C/O)[RETURN]Soclu RUZ (3 C/O)
Destinatie produs	RPM relay[RETURN]RUM relay
Tensiune circuit de comanda	110...240 V c.a.
Cantitate indivizibila de vanzare	10

Suplimentar

Greutate neta	0,004 kg
---------------	----------

Unitati de ambalare

Unitate de masura pentru prima forma de impachetare	PCE
Numar unitati in prima forma de impachetare	1
Inaltime prima forma de impachetare	1 cm
Latime prima forma de impachetare	3,5 cm
Lungime prima forma de impachetare	3,6 cm
Greutate prima forma de impachetare	4 g
Unitate de masura pentru a doua forma de impachetare	BAG
Numar unitati in a doua forma de impachetare	10
Inaltime a doua forma de impachetare	8 cm
Latime a doua forma de impachetare	4 cm
Lungime a doua forma de impachetare	10 cm
Greutate a doua forma de impachetare	49 g
Unitate de masura pentru a treia forma de impachetare	S01
Numar unitati in a treia forma de impachetare	300
Inaltime a treia forma de impachetare	15 cm
Latime a treia forma de impachetare	15 cm
Lungime a treia forma de impachetare	40 cm
Greutate a treia forma de impachetare	1,885 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the products of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Sustenabilitatea ofertei

Stare ofertă sustenabilă	Produs Green Premium
Regulamentul REACH	 Declaratia REACH
Conform REACH fara SVHC	Da
Directiva RoHS UE	Conformitate proactivă (Produs în afara domeniului de aplicare a EU RoHS)  Declaratia RoHS UE
Fara metale grele toxice	Da
Fara mercur	Da
Regulamentul RoHS China	 Declaratia RoHS China
Informatii privind scutirea de la RoHS	 Da
Raport de mediu	 Profilul Ambiental Al Produsului
Profil circularitate	Nu sunt necesare operatii de reciclare speciale
WEEE	În Uniunea Europeana, produsele trebuie reciclate respectand sistemul specific de colectare a deseurilor si nu trebuie sa ajunga in pubelele de colectare a deseurilor menajere.

Garanție contractuală

Garantie	18 luni
----------	---------

Wiring Diagram

