


Product data sheet

Characteristics

NU541144Z

Noua Unica, Priza RJ45 Cat 5E UTP, cu suport
fixare si gheare, 2m, bej

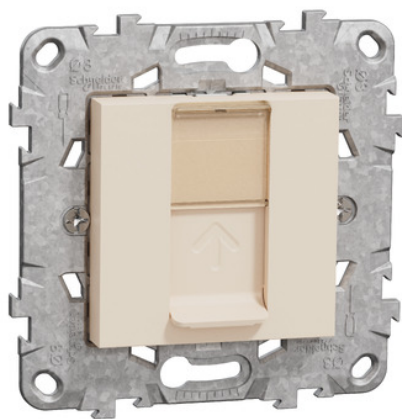

Principal

Gama	Noua Unica
Denumire	Unica (standard estetic)
Tip produs sau componenta	Priza de date
Prezentare dispozitiv	Mecanism cu suport de fixare
Culoare	Bej (RAL 1013)
Tip priza de date	Priza RJ45 8 contacte Cat.5e < 155 MHz
Echipament furnizat	Suport eticheta Clapeta de protectie

Suplimentar

Tip de retea de comunicatie	1000BASE-T
Port protocol de comunicatie	ATM 155 Mbps
Numar module	2 module
Numar priza	1
Tip amprenta	Infraplus
Tipul conectorului	S-One
Tip manta cablu	U/UTP
Organizarea cablurilor	Pereche torsadata, neecranata
Conexiuni - borne	Clic
Mod de fixare	Gheare lungi
Directie de instalare	Drept
Material	ASA + PC: capac mecanism ABS (nitril acrilic butadiena - stirena): capac mecanism Zamak: suport de fixare
Adancime	36 mm
Latime	70,9 mm
Inaltime	70,9 mm
Adancime de montaj	25 mm
Rezistenta la agenti chimici	Rezistent la alcool (70%) Rezistent la alcool (96%) Rezistent la acid A-lactic Rezistent la amoni cuaternar diluat Rezistent la inalbitor diluat Rezistent la amoniac diluat Rezistent la apa cu sapun Rezistent la detergent de cristal Rezistent la peroxid de hidrogen 10 volume Rezistent la hexan

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Mediu

Grad de protectie IP	IP40 IP20
Grad de protectie IK	IK01
Temperatura ambietala de utilizare	15...30 °C -25...55 °C
Temperatura ambietala pentru depozitare	-25...55 °C
Caracteristica de mediu	Benzina Fluid de curatare a geamurilor Decolorant Ulei Alcool Sapun lichid Rezistent UV Acetona
Standarde	ISO 8877

Unitati de ambalare

Unitate de masura pentru prima forma de impachetare	PCE
Numar unitati in prima forma de impachetare	1
Inaltime prima forma de impachetare	5 cm
Latime prima forma de impachetare	7,5 cm
Lungime prima forma de impachetare	7,5 cm
Greutate prima forma de impachetare	70 g
Unitate de masura pentru a doua forma de impachetare	BB1
Numar unitati in a doua forma de impachetare	10
Inaltime a doua forma de impachetare	8,2 cm
Latime a doua forma de impachetare	19,7 cm
Lungime a doua forma de impachetare	22,6 cm
Greutate a doua forma de impachetare	805 g
Unitate de masura pentru a treia forma de impachetare	S03
Numar unitati in a treia forma de impachetare	50
Inaltime a treia forma de impachetare	30 cm
Latime a treia forma de impachetare	30 cm
Lungime a treia forma de impachetare	40 cm
Greutate a treia forma de impachetare	4,466 kg

Sustenabilitatea ofertei

Stare ofertă sustenabilă	Produs Green Premium
Regulamentul REACH	 Declaratia REACH
Conform REACH fara SVHC	Da
Directiva RoHS UE	Conform  Declaratia RoHS UE
Fara metale grele toxice	Da
Fara mercur	Da
Regulamentul RoHS China	 Declaratia RoHS China
Informatii privind scutirea de la RoHS	 Da
Raport de mediu	 Profilul Ambiental Al Produsului
Profil circularitate	Nu sunt necesare operatii de reciclare speciale

Garanție contractuală

Garantie	18 luni
----------	---------