


Product data sheet

Characteristics

NU546218Z

Noua Unica, Priza TV tata individuala, cu suport fixare si gheare, 2m, alb

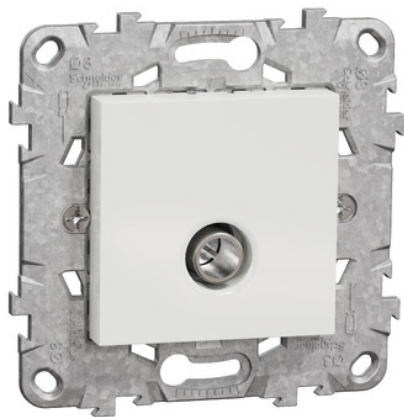

Principal

Gama	Noua Unica
Tip produs sau componenta	Priza TV
Aplicatie a dispozitivului	Suport media Comunicare
Prezentare dispozitiv	Mecanism cu suport de fixare
Tip priza TV	Individuala
Culoare	Alb (RAL 9003)

Suplimentar

Conector TV	Tata IEC 9,52 mm
Atenuare traseu	1,5 dB TV semnal5...2200 MHz
Flux de curent c.c.	Da
Numar pe linie	1
Numar module	2 module
Material	ASA + PC: capac mecanism Termoplastic stabilizat ABS-UV: capac mecanism Zamak: suport de fixare
Tratament suprafata	Netratat
Finisare suprafata	Lucios
Marcaj	Fara marcaj
Mod de fixare	Gheare lungi
Adancime	28 mm
Latime	70,9 mm
Inaltime	70,9 mm
Adancime de montaj	18 mm
Greutate neta	0,068 kg
Rezistenta la agenti chimici	Rezistent la alcool (70%) Rezistent la alcool (96%) Rezistent la acid A-lactic Rezistent la amoni cuaternar diluat Rezistent la inalbitor diluat Rezistent la amoniac diluat Rezistent la apa cu sapun Rezistent la detergent de cristal Rezistent la peroxid de hidrogen 10 volume Rezistent la hexan

The information provided in this documentation contains general descriptions and/or technical characteristics of the products of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Mediu

Grad de protectie IP	IP20
Grad de protectie IK	IK01
Temperatura ambientala de functionare	-5...35 °C
Temperatura ambietala pentru depozitare	-5...50 °C
Caracteristica de mediu	Benzina Fluid de curatare a geamurilor Acetona Ulei Rezistent UV Alcool Sapun lichid Decolorant
Standarde	EMC Directiva de compatibilitate electromagnetica EN 50083-2 EN 50083-4 EN 50083-1

Unitati de ambalare

Unitate de masura pentru prima forma de impachetare	PCE
Numar unitati in prima forma de impachetare	1
Inaltime prima forma de impachetare	5,0 cm
Latime prima forma de impachetare	7,5 cm
Lungime prima forma de impachetare	7,5 cm
Greutate prima forma de impachetare	78,0 g
Unitate de masura pentru a doua forma de impachetare	BB1
Numar unitati in a doua forma de impachetare	10
Inaltime a doua forma de impachetare	8,2 cm
Latime a doua forma de impachetare	19,7 cm
Lungime a doua forma de impachetare	22,6 cm
Greutate a doua forma de impachetare	885,0 g
Unitate de masura pentru a treia forma de impachetare	S04
Numar unitati in a treia forma de impachetare	120
Inaltime a treia forma de impachetare	30,0 cm
Latime a treia forma de impachetare	40,0 cm
Lungime a treia forma de impachetare	60,0 cm
Greutate a treia forma de impachetare	11,323 kg

Sustenabilitatea ofertei

Stare ofertă sustenabilă	Produs Green Premium
Regulamentul REACH	 Declaratia REACH
Directiva RoHS UE	Conform  Declaratia RoHS UE
Fara metale grele toxice	Da
Fara mercur	Da
Regulamentul RoHS China	 Declaratia RoHS China
Informatii privind scutirea de la RoHS	 Da
Raport de mediu	 Profilul Ambiental Al Produsului
Profil circularitate	 Informatii Privind Sfarsitul Duratei De Viata

Garanție contractuală

Garantie	18 luni
----------	---------