


Product data sheet

Characteristics

OVA48941

Smartbeam IP42 ST Dicube 220lm 1,5h

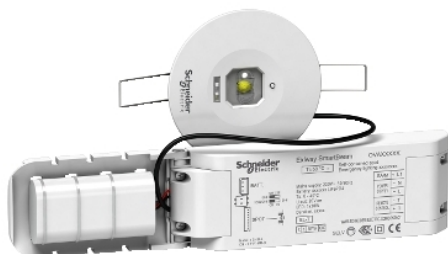

Principal

Gama	Exiway
Nume produs	Exiway Smartbeam DiCube
Tip produs sau componenta	Emergency luminaire
Aplicatie a dispozitivului	Iluminare
Funcție	Addressable
Operational mode	Mentinut Nementinut
Numar de baterii	1 x 3,2 V 1,5 Ah LiFePO4
Sursa de lumina	1 x LED 10 W

Suplimentar

Suport de montare	False ceiling
[Ue] tensiune nominala de functionare	230 V c.a. 50/60 Hz
Puterea consumata in VA	3,9 VA nementinut 8,3 VA mentinut
Puterea consumata in W	0,43 W nementinut 3,5 W mentinut
Clasa de izolatie electrica	Clasa II
Port protocol de comunicatie	DALI
Durata de viata a LED-ului	100000 H
Funcție disponibilă	Automatic addressing of emergency lighting by means of control unit
Autonomie	1.5 h
Timp de incarcare	12 H
Iluminare	0,5 lux
Material	Termoplastic autostingere
Inaltime	55,8 mm
Adancime	23,8 Mm 31,5 mm
Latime	256,6 mm
Diametru	Light fitting:90 mm
Greutate neta	292 g

Mediu

Grad de protectie IP	IP42
Grad de protectie IK	IK04
Rezistenta la foc	V2
Rezistenta la foc	850 °C
Certificari produs	ENEC[RETURN]UE

The information provided in this documentation contains general descriptions and/or technical characteristics of the products of the company Schneider Electric. This information is not intended to be used as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Temperatura ambientală de utilizare	0...40 °C
Standarde	SR EN 60598-1 SR EN 62034 UL 94 EN 60598-2-22 SR EN 62471 grupul 1 SR EN 60695-2-10 IEC 62386-202 IEC 62386-102

Unitati de ambalare

Unitate de masura pentru prima forma de impachetare	PCE
Numar unitati in prima forma de impachetare	1
Înălțime prima forma de impachetare	5,6 cm
Latime prima forma de impachetare	27,8 cm
Lungime prima forma de impachetare	18,4 cm
Greutate prima forma de impachetare	388,0 g
Unitate de masura pentru a doua forma de impachetare	S03
Numar unitati in a doua forma de impachetare	10
Înălțime a doua forma de impachetare	30 cm
Latime a doua forma de impachetare	30 cm
Lungime a doua forma de impachetare	40 cm
Greutate a doua forma de impachetare	4,315 kg

Sustenabilitatea ofertei

Directiva RoHS UE	Conform Declaratia RoHS UE
Fara metale grele toxice	Da
Fara mercur	Da
Regulamentul RoHS China	Declaratia RoHS China
Informatii privind scutirea de la RoHS	Da
Raport de mediu	Profilul Ambiental Al Produsului
Profil circularitate	Informatii Privind Sfarsitul Duratei De Viata
WEEE	În Uniunea Europeana, produsele trebuie reciclate respectand sistemul specific de colectare a deseurilor si nu trebuie sa ajunga in pubelele de colectare a deseurilor menajere.

Garanție contractuală

Garantie	18 luni
----------	---------