


Product data sheet

Characteristics

NSYCRS100W240V

Climasys Ultra thin resistance heater low starting current 90W 240V 280x450mm

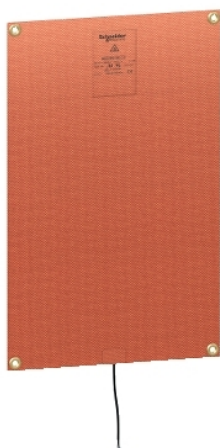

Main

Range	ClimaSys
Product name	ClimaSys CR
Product or component type	Ultra thin resistance heater
Power range	90 W
Input voltage	240 V AC 50/60 Hz
Electrical connection	Cable length: 2 m

Complementary

Operating position	Horizontal Vertical
Ambient air temperature for operation	-60...70 °C
Temperature setting range	-40...70 °C
Material	Silicone rubber
Height	External: 260 mm
Width	External: 440 mm
Depth	1.6 mm external:
Device composition	6 self-adhesive Velcro pads 6 plastic spacers 4 Telequick nuts 4 clip-on nuts Fixing accessories
Condition of use	Air sealed enclosure Electrical protection is needed Heaters must be installed with a thermal controller
Fixing mode	By 4 screws
Mounting support	DIN rail Telequick mounting plate Adhesive Velcro Standard mounting plate

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.0 cm
Package 1 Width	42.5 cm
Package 1 Length	70.0 cm
Package 1 Weight	740.0 g
Unit Type of Package 2	PAM
Number of Units in Package 2	50
Package 2 Height	160.0 cm
Package 2 Width	100.0 cm

Package 2 Length	120.0 cm
Package 2 Weight	65.0 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile
Circularity Profile	No need of specific recycling operations
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

Contractual warranty

Warranty	18 months
----------	-----------