


Product data sheet

Characteristics

NSYSMBCE10

Spacial SM brush flexible cable entry gaskets -
34 mm - 1000 mm enclosure

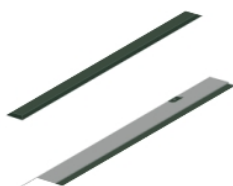

Main

Range	Spacial
Product or component type	Brush gasket
Accessory / separate part category	Cable management accessory
Device application	Multi-purpose
Range compatibility	Spacial Spacial SM compact enclosure
Device composition	2 gasket
Quantity per set	Set of 1

Complementary

Mounting support	Standard cable gland plate
Fixing mode	Clipped
Height	35 mm
Width	1000 Mm nominal: 900 mm
Depth	34 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.0 cm
Package 1 Width	8.0 cm
Package 1 Length	96.0 cm
Package 1 Weight	576.0 g
Unit Type of Package 2	PAM
Number of Units in Package 2	100
Package 2 Height	103.0 cm
Package 2 Width	100.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	94.0 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration

RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Logistical informations

Country of origin	FR
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------