


Product data sheet

Characteristics

NSYSPF3100

Spacial SF front plinth - 100x300 mm

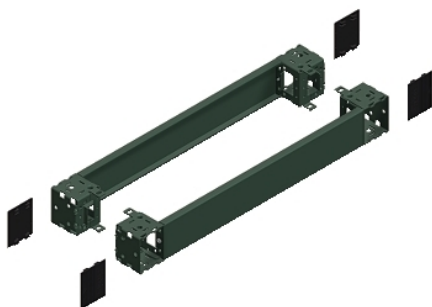

Main

Range	Spacial
Accessory / separate part category	Enclosure accessory
Product or component type	Plinth front
Application	Prisma application Multi-purpose
Nominal dimensions of the housing	-
Device composition	Fixing elements 4 corner cover 1 front panel 1 rear panel 4 corner
Range compatibility	Spacial Spacial SF Spacial Spacial SM Prisma Prisma PH
Mounting support	Plinth side panels

Complementary

Fixing mode	By fixing element - on structure location
Colour	Grey (RAL 7022)
Surface finish	Epoxy-polyester powder
Permanent permissible load	1300 kg
Height	100 mm
Width	Nominal: 300 mm

Environment

IP degree of protection	IP20 (complete plinth)
IK degree of protection	IK10

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	11.500 cm
Package 1 Width	20.000 cm
Package 1 Length	31.500 cm
Package 1 Weight	3.194 kg
Unit Type of Package 2	S04
Number of Units in Package 2	5
Package 2 Height	30 cm
Package 2 Width	40 cm
Package 2 Length	60 cm
Package 2 Weight	16.620 kg
Unit Type of Package 3	P12
Number of Units in Package 3	20
Package 3 Height	45.000 cm

Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	78.480 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Logistical informations

Country of origin	FR
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------