


Product data sheet

Characteristics

NSYSPF7200

Spacial SF/SM front plinth - 200x700 mm

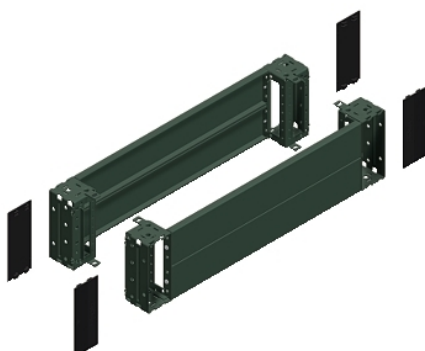

Main

Range	Spacial
Accessory / separate part category	Enclosure accessory
Product or component type	Plinth front
Application	Multi-purpose
Nominal dimensions of the housing	-
Device composition	Fixing elements 4 corner cover 4 corner 2 front panel 2 rear panel
Range compatibility	Spacial Spacial SFP
Mounting support	Plinth side panels

Complementary

Fixing mode	By fixing element - on structure location
Colour	Grey (RAL 7022)
Surface finish	Epoxy-polyester powder
Permanent permissible load	1300 kg
Height	200 mm
Width	700 mm nominal:

Environment

IP degree of protection	IP20 (complete plinth)
IK degree of protection	IK10

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	21.1 cm
Package 1 Width	19.2 cm
Package 1 Length	70.8 cm
Package 1 Weight	10.0 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes

Environmental Disclosure	 Product Environmental Profile
Circularity Profile	No need of specific recycling operations
Contractual warranty	
Warranty	18 months