


Product data sheet

Characteristics

NSYSTMP6080

Spacial SF/SM perforated mounting plate - 800 mm

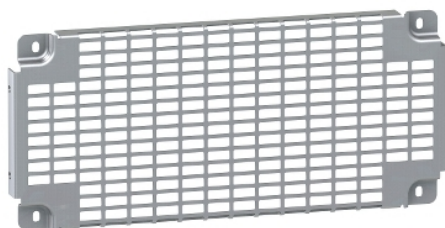

Main

| | |
|------------------------------------|--|
| Range | Spacial |
| Accessory / separate part category | Mounting accessory |
| Product or component type | Mounting plate |
| Device application | Multi-purpose |
| Enclosure nominal dimensions | - |
| Mounting plate description | Telequick perforated |
| Range compatibility | Spacial Spacial SF Spacial Spacial SM Spacial Spacial SFX Spacial Spacial SMX |
| Device composition | 1 mounting plate Fixing elements |
| Quantity per set | Set of 1 |
| Material | Steel |
| Surface finish | Zinc coated |

Complementary



| | |
|--------------------|---|
| Fixing mode | By fixing element - on structure location |
| Height | 575 Mm fixing centers: 600 mm |
| Width | 800 Mm nominal: 708 mm |
| Cut-out dimensions | 11 x 26 mm |

Packing Units

| | |
|------------------------------|---------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 2.8 cm |
| Package 1 Width | 71.0 cm |
| Package 1 Length | 60.0 cm |
| Package 1 Weight | 3.7 kg |

Offer Sustainability

| | |
|--------------------------|--|
| Sustainable offer status | Green Premium product |
| REACH Regulation | REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| China RoHS Regulation | China RoHS Declaration |

| | |
|-----------------------------|---|
| RoHS exemption information |  Yes |
| Environmental Disclosure |  Product Environmental Profile |
| Circularity Profile | No need of specific recycling operations |
| Contractual warranty | |
| Warranty | 18 months |