


Product data sheet

Characteristics

VW3A3407

encoder interface card with push-pull outputs -
24 V DC

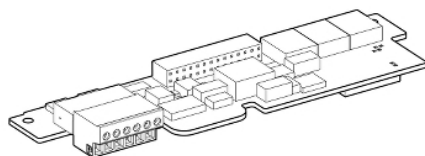

Main

Range of product	Altivar
Product or component type	Encoder interface card
Range compatibility	Altivar 61Q Altivar 71Q Altivar 71 Altivar 61 Altivar Lift
Discrete output type	Push-pull
[Us] rated supply voltage	24 V DC (voltage limits: 20...30 V)
Number of pulses per revolution	10000 for ATV71H.....383 5000 for all ATV61 drives 5000 for ATV71H...M3 5000 for ATV71H...M3X 5000 for ATV71H...N4

Complementary

Maximum supply current	0.175 A
Protection type	Overload protection Short-circuit protection
Maximum cable distance between devices	500 m
Maximum operating frequency	300 kHz
Input signal	A B Compliment of A Compliment of B/AB/A
Input impedance	1000 Ohm
Voltage state 0 guaranteed	<= 1.5 V
Voltage state 1 guaranteed	> 11.5...< 25 V
Electrical connection	Terminal, connection capacity: 0.2 mm² (AWG 24) <500 m cable length, encoder, 100 mA at 14 V

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.500 cm
Package 1 Width	17.000 cm
Package 1 Length	23.000 cm
Package 1 Weight	142.000 g
Unit Type of Package 2	S03
Number of Units in Package 2	7
Package 2 Height	30.000 cm
Package 2 Width	30.000 cm
Package 2 Length	40.000 cm
Package 2 Weight	1.503 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Logistical informations

Country of origin	ID
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------