

Product data sheet

Characteristics

XCMD2161L1

Limit switch, Limit switches XC Standard, XCMD, forked arm with rollers 2 tracks, 1NC+1 NO, snap, 1 m



Main

Range of product	Telemecanique Limit switches XC Standard
Series name	Standard format
Product or component type	Limit switch
Device short name	XCMD
Sensor design	Miniature
Material	Metal
Body material	Zamak
Head material	Zamak

Complementary

Cable length	1 m
Width	30 mm
Height	50 mm
Depth	16 mm


Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	14.288 cm
Package 1 Width	14.288 cm
Package 1 Length	14.288 cm
Package 1 Weight	317.515 g

Offer Sustainability

Sustainable offer status	Green Premium product
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes


Dimensions

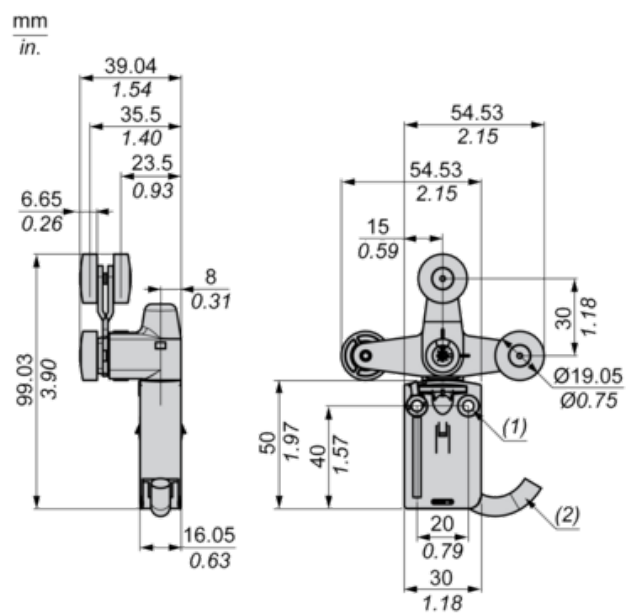

- (1) 2 fixing holes $\varnothing 4.2$ mm, counterbored $\varnothing 8$ mm by 4 mm deep.
- (2) External diameter of cable 7.5 mm.

Mounting


Sweep of Connecting Cable

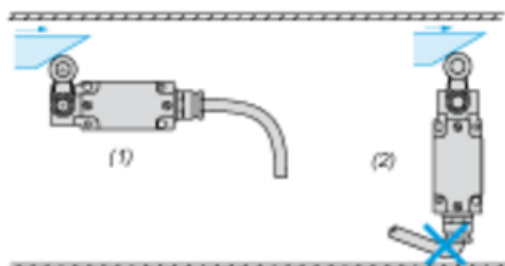

- (1) Recommended
(2) To be avoided


Mounting with Rotary Heads and Levers

Type of Cam

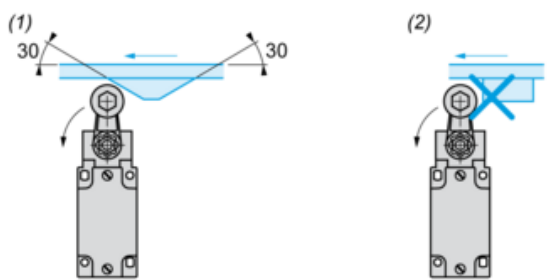

- (1) Recommended
(2) To be avoided


Setting-up with Head ZCE01 and ZCE09

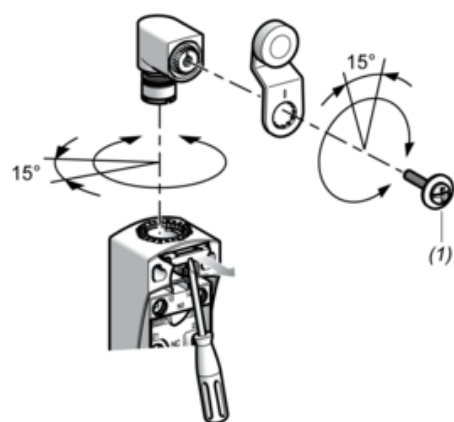

- (1) Tightening torque (Min : 1) (Max : 1.5)

Wiring Diagram

2-pole NC + NO Snap Action

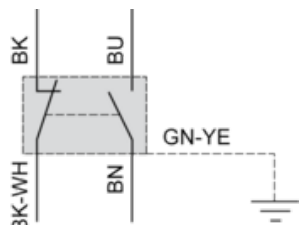

(BK) Black

(BK-WH) Black White

(BU) Blue

(BN) Brown

(GN-YE) Green Yellow