

Product data sheet

Characteristics

XVEC21P

BASE UNIT W/SCREW COVER+IP54 SEAL KIT



Main

Range of product	Harmony XVE Optimum
Product or component type	Base unit kit
Kit composition	Base unit Screw fixing cover 5 seals for illuminated/audible unit 1 seal for fixing base XVEZ13
Component name	XVE

Complementary

Mounting diameter	70 mm
Assembly style	Customer assembly
Marking	CE
Terminals description ISO n°1	(COM-3)PW (COM-1)PW (COM-4)PW (COM-2)PW (COM-5)PW (GND)GROUND
Net weight	0.12 kg

Environment

Standards	EN/IEC 60947-1 EN/IEC 60947-5-1
Product certifications	CSA[RETURN]UL[RETURN]CCC
Ambient air temperature for storage	-40...70 °C
Ambient air temperature for operation	-25...55 °C
Electrical shock protection class	Class I aluminium tube mounting conforming to IEC 61140 Class I plastic tube mounting conforming to IEC 61140
Protective treatment	TC
IP degree of protection	IP54 (outdoor) conforming to IEC 60529


Contractual warranty

Warranty	18 months
----------	-----------

Indicator Bank

Dimensions

Below drawing shows the minimum configuration of the product. Select the number of stages according to the product characteristics in order to get b dimension.

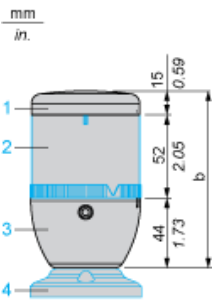

- (1) Cover (supplied with base unit)
- (2) Illuminated units XVEC•• or audible unit XVEC9•, to be ordered separately
- (3) Base unit
- (4) Fixing base, to be ordered separately

Number of units (ref. 2)	b in mm	b in in.
1 unit	111	4.37
2 units	163	6.42
3 units	215	8.46
4 units	267	10.51
5 units	319	12.56

Indicator Bank

Wiring Diagram

