


## Product data sheet

### Characteristics

# XZCC12FDM40V

female, M12, 4-pin, straight connector - cable gland Pg 7

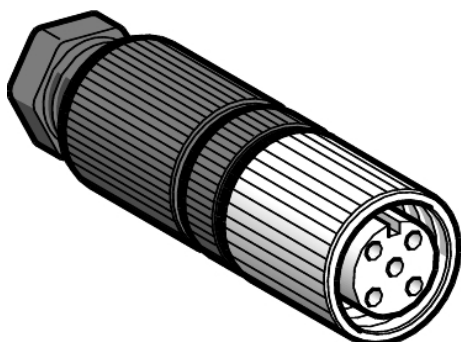

### Main

Range of product	Telemecanique Cabling components
Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Straight female connector M12, 4 pins
Collar material	Metal
Status LED	Without
Cable connection	Axial vampire clip / wire size <0.5 mm <sup>2</sup>

### Complementary

Cable gland type	Pg 7
Cable connector fixing	Screw-on
[Ue] rated operational voltage	< 60 V AC/DC
[In] rated current	4 A
Enclosure material	Plastic
Minimum insulating resistance	1 GΩ
Contact resistance	8000 μOhm
Net weight	0.015 kg

### Environment

IP degree of protection	IP67
Ambient air temperature for operation	-25...70 °C

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1

### Contractual warranty

Warranty	18 months
----------	-----------