

Product data sheet

Characteristics

XZCC12MDB50R

male, M12, 5-pin, shielded straight connector



Main

Range of product	Telemecanique Cabling components
Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Straight male connector M12, 5 pins
Collar material	Metal
Status LED	Without
Cable connection	Spring / wire size <0.5 mm ² / clamping capacity 4... 8 mm

Complementary

Cable connector fixing	Screw-on
[Ue] rated operational voltage	30 V AC 36 V DC
[In] rated current	4 A
Enclosure material	Metal
Minimum insulating resistance	1000 GΩ
Contact resistance	8000 μOhm
Net weight	0.02 kg




Environment

IP degree of protection	IP67
Ambient air temperature for operation	-40...85 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.000 cm
Package 1 Width	3.500 cm
Package 1 Length	5.000 cm
Package 1 Weight	38.000 g
Unit Type of Package 2	S02
Number of Units in Package 2	100
Package 2 Height	15 cm
Package 2 Width	30 cm
Package 2 Length	40 cm
Package 2 Weight	4.099 kg


Offer Sustainability

REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	 Yes

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

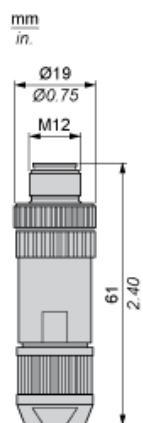

(1) Cable gland : no. 7 plastic (Pg 7)

Connections and Schemes

