

Product data sheet

Characteristics

XZCC8FDM40S

female, M8, 4-pin, straight connector - cable gland M9.5 x 1



Main

Range of product	Telemecanique Cabling components
Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Straight female connector M8, 4 pins
Collar material	Metal
Status LED	Without
Cable connection	Solder terminal / wire size <0.25 mm ² / clamping capacity 5 mm

Complementary

Cable gland type	M9.5
Cable connector fixing	Screw-on
[Ue] rated operational voltage	60 V AC 75 V DC
[In] rated current	4 A
Enclosure material	Plastic
Minimum insulating resistance	1 GΩ
Contact resistance	5000 μOhm
Net weight	0.01 kg

Environment

IP degree of protection	IP67
Ambient air temperature for operation	-40...85 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.600 cm
Package 1 Width	1.900 cm
Package 1 Length	7.900 cm
Package 1 Weight	9.000 g
Unit Type of Package 2	S01
Number of Units in Package 2	50
Package 2 Height	15 cm
Package 2 Width	15 cm
Package 2 Length	40 cm
Package 2 Weight	901.000 g


Offer Sustainability

REACH Regulation	 REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
RoHS exemption information	 Yes

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

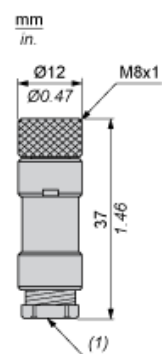

(1) Cable gland : M9.5 x 1

Connections and Schemes

