


## Product data sheet

### Characteristics

# XZCPA0941L5

pre-wired connectors XZ - straight female - M8  
- 4 pins - cable PVC 5m

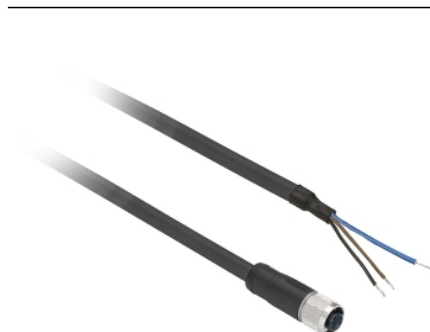

### Main

Range of product	Telemecanique Cabling components
Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	Application

### Complementary

Electrical connection	Straight female connector M8, 4 pins
Cable connector fixing	Screw-on
Collar material	Stainless steel 316L
Status LED	Without
Cable length	5 m
Cable outer diameter	5.3 mm
Cable composition	4 x 0.34 mm <sup>2</sup>
Wire insulation material	PVC
[Ue] rated operational voltage	75 V DC
[In] rated current	4 A
Contact resistance	5000 µOhm
Minimum insulating resistance	1 GΩ
Net weight	0.4 kg




### Environment

IP degree of protection	IP68
Ambient air temperature for operation	-25...85 °C static
Ambient air temperature for storage	-35...100 °C

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.000 cm
Package 1 Width	17.500 cm
Package 1 Length	17.500 cm
Package 1 Weight	153.000 g
Unit Type of Package 2	S02
Number of Units in Package 2	20
Package 2 Height	15.000 cm
Package 2 Width	30.000 cm
Package 2 Length	40.000 cm
Package 2 Weight	3.348 kg


Offer Sustainability

REACH Regulation	 <a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	 <a href="#">Yes</a>

Contractual warranty

Warranty	18 months
----------	-----------

## Dimensions

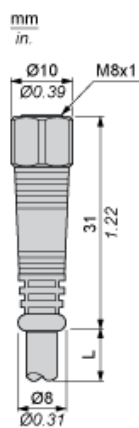


L : Length of cable

---

## Connections and Schemes

---

### Connector

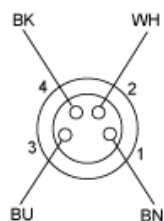

BN : Brown  
BK : Black  
BU : Blue  
WH : White