


Product data sheet

Characteristics

ZC1AC005

Limit switch head, Limit switches XC Standard, ZC1AC, end ball bearing plunger

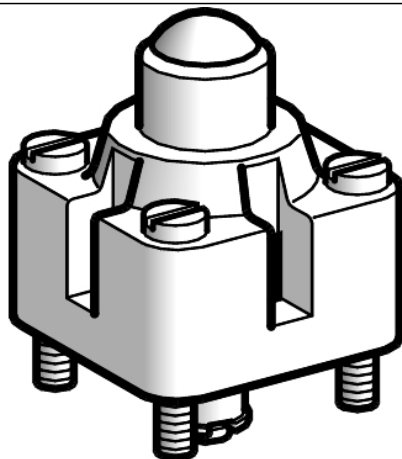

Main

Range of product	OsiSense XC
Series name	Special format
Product or component type	Limit switch head
Device short name	ZC1AC
Head type	Plunger head
Product compatibility	XC1AC
Movement of operating head	Linear
Type of operator	Spring return ball bearing plunger metal
Switch actuation	By 30° cam
Type of approach	Multi-directional approach
Positive opening	Without

Complementary

Net weight	0.05 kg
------------	---------


Environment

Ambient air temperature for operation	-25...70 °C
Ambient air temperature for storage	-40...70 °C
Environmental characteristic	Standard environment

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5 cm
Package 1 Width	3 cm
Package 1 Length	6 cm
Package 1 Weight	53 g

Offer Sustainability

REACH Regulation	 REACH Declaration
EU RoHS Directive	Not applicable, out of EU RoHS legal scope