


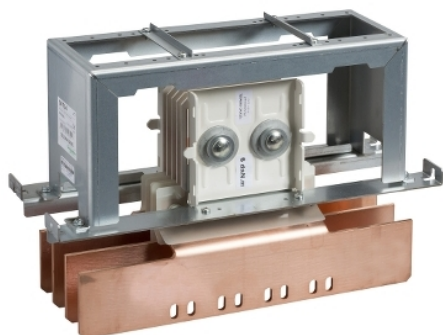

Main

Range	PrismaSeT
Range of product	PrismaSeT P
Product or component type	Interface and connection Canalis
Product name	PrismaSeT PrismaSeT P enclosure
Accessory / separate part category	Interface accessory
Standards	IEC 61439-2, inside enclosure IEC 61439-1, inside enclosure
Product certifications	ASTA

Complementary

Cubicle-device connection	KT with Canalis
Poles description	3P
Installation description	Cubicle - width 650 mm
Cubicle depth	400 mm: front 400 + 400 mm: rear
Installed device	ComPact: drawout NS630b...1000 - control: direct front rotary handle vertical installation ComPact: drawout NS1250 - control: direct front rotary handle vertical installation ComPact: drawout NS630b...1000 - control: motor mechanism vertical installation ComPact: drawout NS1250 - control: motor mechanism vertical installation ComPact: drawout NS630b...1000 - control: toggle vertical installation ComPact: drawout NS1250 - control: toggle vertical installation ComPact: fixed NS630b...1000 - control: toggle vertical installation ComPact: fixed NS1250 - control: toggle vertical installation ComPact: fixed NS630b...1000 - control: direct front rotary handle vertical installation ComPact: fixed NS1250 - control: direct front rotary handle vertical installation ComPact: fixed NS630b...1000 - control: motor mechanism vertical installation ComPact: fixed NS1250 - control: motor mechanism vertical installation ComPact: fixed NS1600 - control: toggle vertical installation ComPact: fixed NS1600 - control: direct front rotary handle vertical installation ComPact: fixed NS1600 - control: motor mechanism vertical installation ComPact: drawout NS1600 - control: direct front rotary handle vertical installation ComPact: drawout NS1600 - control: motor mechanism vertical installation ComPact: drawout NS1600 - control: toggle vertical installation Masterpact: fixed NT06...10 - control: toggle vertical installation Masterpact: fixed NT06...10 - control: motor mechanism vertical installation Masterpact: fixed NT12 - control: toggle vertical installation Masterpact: fixed NT12 - control: motor mechanism vertical installation Masterpact: fixed NT16 - control: toggle vertical installation Masterpact: fixed NT16 - control: motor mechanism vertical installation
[I _e] rated operational current	1600 A
Colour	Natural
Height	410 mm
Width	600 mm
Depth	285 mm
Net weight	27.2 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Quantity per set	Set of 1
------------------	----------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	44.0 cm
Package 1 Width	25.0 cm
Package 1 Length	61.0 cm
Package 1 Weight	27.75 kg
Unit Type of Package 2	P06
Number of Units in Package 2	2
Package 2 Height	58.0 cm
Package 2 Width	60.0 cm
Package 2 Length	80.0 cm
Package 2 Weight	61.5 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Circularity Profile	No need of specific recycling operations