

Product data sheet

Characteristics

XACB065

Prazna viseča krmilna postaja XAC-B - 6
navpičnih odprtín



Glavno

Serijska izdelka	Harmony XAC
Izdelek ali sestavni del	Obesna krmilna postaja
Kratko ime naprave	XACB

Komplementarno

Tip krmilne postaje	Dvojna izoliranost
Material omare	Poliester okrepljen s steklom
Tip električnega tokokroga	Krmilno vezje Močnostni tokokrog
Tip omare	Prazna omara
Število izrezov	6 izrezov
Barva krmilne postaje	Rumena
Kabelska uvodnica	Gumen trak s stopničastim vhodom 22...35 mm
Zaščitna letev	Brez
Vertikalni operatorski izklopni center	40 Mm
Standardi	CSA C22.2 št. 14 EN/IEC 60947-5-1
Certifikati izdelkov	CSA tip 4
Zaščitna obdelava	TH
Temperatura okoliškega zraka za delovanje	-25...70 °C
Temperatura okoliškega zraka za skladiščenje	-40...70 °C
Odpornost proti vibracijam	15 gn (f = 10...500 Hz) v skladu s/z IEC 60068-2-6
Odporno proti udarcu	100 gn v skladu s/z IEC 60068-2-27
Prenapetostna kategorija	Razred II v skladu s/z IEC 61140
IP stopnja zaščite	IP65 v skladu s/z IEC 60529
IK stopnja zaščite	IK08 v skladu s/z EN 50102
Mehanska vzdržljivost	1000000 Ciklov
Teža izdelka	1,36 Kg

Embalazna enota

Embalazna enota Paketa 1	PCE
Število enot v Paketu 1	1
Paket 1 Višina	9,0 Cm
Paket 1 Širina	10,0 Cm
Paket 1 Dolžina	70,0 Cm
Paket 1 Teža	1,52 Kg

Trajnost ponudbe


Uredba REACH	Izjava REACH
REACH, brez snovi SVHC	Da
Direktiva EU ROHS	Proaktivno zagotavljanje skladnosti (izdelek je zunaj področja uporabe direktive EU RoHS) Izjava EU RoHS
Brez strupenih težkih kovin	Da
Brez živega srebra	Da
Uredba o RoHS za Kitajsko	Izjava O RoHS Za Kitajsko
Informacije o izvzetju iz RoHS	Da

Pogodbena garancija

Garancija	18 mesecev
-----------	------------

Dimensions

Below drawing shows a product with 6 cut-outs. Select the number of cut-outs according to the product characteristics in order to get b, b1 and c dimensions.

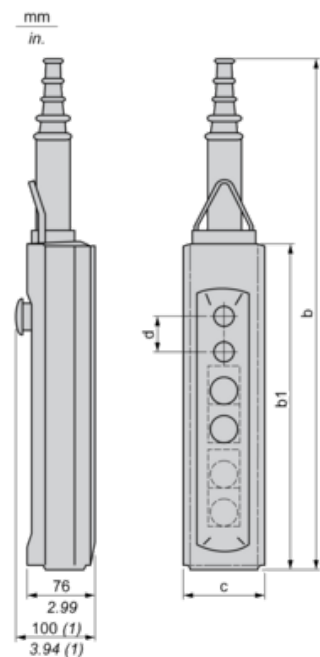

(1) With mushroom head operator


Dimensions in mm

Number of cut-outs	2	4	6	8	12
b	409	499	589	679	679
b1	220	310	400	490	490
c	98	98	98	98	98
d	40	40	40	40	30

Dimensions in in.

Number of cut-outs	2	4	6	8	12
b	16.10	19.64	23.19	26.73	26.73
b1	8.66	12.20	15.75	19.29	19.29
c	3.86	3.86	3.86	3.86	3.86
d	1.57	1.57	1.57	1.57	1.18


Protective cable sleeves

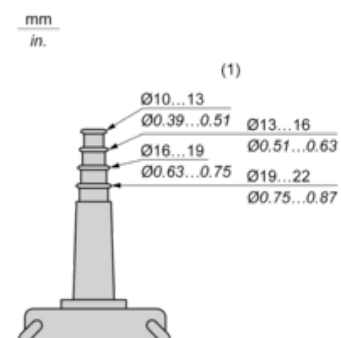

(1) Internal ø


Control of Single-Speed Reversing Motor

With XESD1181 contact block, to be ordered separately

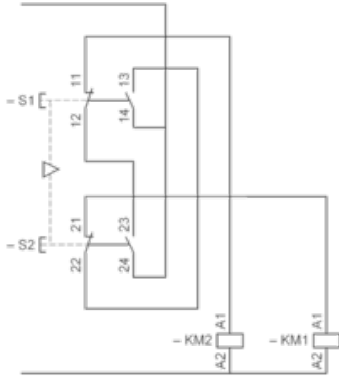

Control of 2-Speed Reversing Motor


With XESD1281 contact block, to be ordered separately

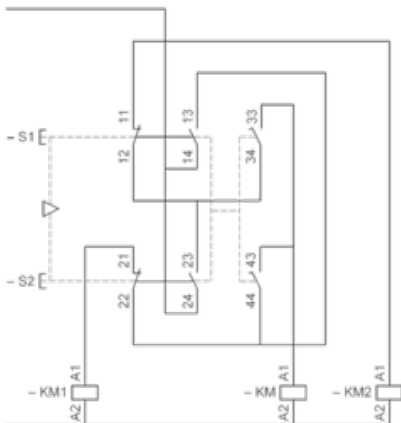


KM High speed contactor

Control of Single-Speed Reversing Motor 2-Phase Switching

With XESD1191 contact block, to be ordered separately

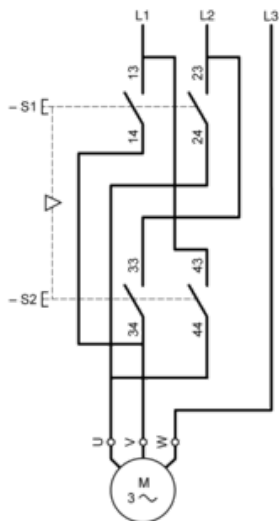


Combined with 3-pole isolating block XACS399 or XACS3991, shown in the unoperated position (pendant station "supplied"), fitted with key release trigger action latching Emergency stop operator.

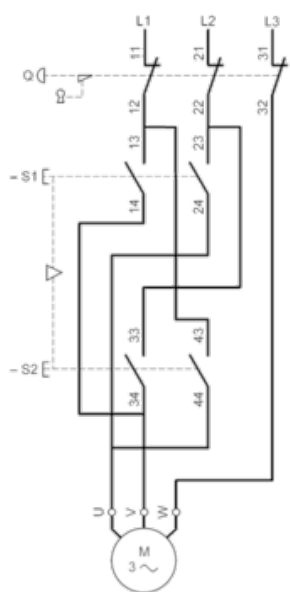


Control of 2-Speed Reversing Motor 2-Phase Switching

With XESD1291 contact block, to be ordered separately

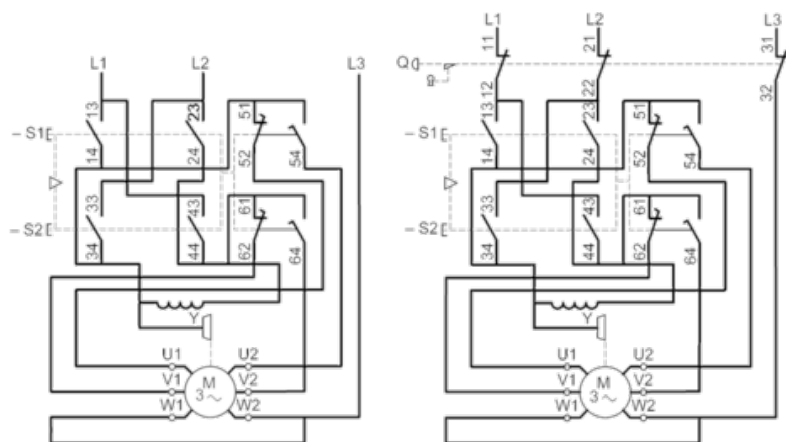

Control of Single-Speed Reversing Motor 3-Phase switching, Reversing by 2-Phase Inversion

With XESD2201 contact block, to be ordered separately

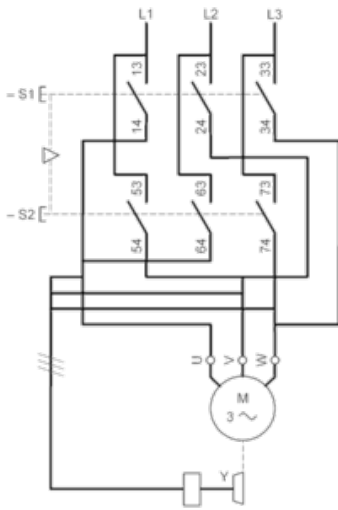

Control of Single-Speed Reversing Motor 3-Phase switching, Reversing by 2-Phase Inversion

With XESD2241 contact block, to be ordered separately

