

Product data sheet

Characteristics

XVUC25

Ø 60 mm osvetlitvena LED enota - stalna - oran. - IP65 - 24 V AC/DC



Glavno

Serijska izdelka	Harmony XVU
Izdelek ali sestavni del	Modularni signalni semafor
Tip signalnega svetilnika	Led enota
Montažni premer	60 Mm
Ime komponente	XVU
Izvor svetlobe	LED, Oranžna
Aplikacija naprave	Pakirni stroj Strojna orodja Avtomobilska

Komplementarno

Tip signalizacije	Stalno
Slog sestavljanja	Sestava na strani stranke, do 5 enot Do 4 enote z zvočnim signalom
Material	PC (polikarbonat) V-2 v skladu s/zUL 94 PC (polikarbonat) V-0 v skladu s/zUL 94
[Us] Nazivna napajalna napetost	24 V AC/DC
Maksimalna izgube moči v W	2 W
Poraba toka	<= 40 mA
Tip signalizacije	Stalno
Dolžina	50 Mm
Teža izdelka	0,064 Kg

Okolje

Certifikati izdelkov	CSA[RETURN]UL[RETURN]CE
Temperatura okoliškega zraka za skladiščenje	-40...70 °C
IP stopnja zaščite	IP65
Temperatura okoliškega zraka za delovanje	-25...50 °C
Odpornost proti vibracijam	2 Gn

Embalažna enota

Embalažna enota Paketa 1	PCE
Število enot v Paketu 1	1
Paket 1 Višina	9 Cm
Paket 1 Širina	13,3 Cm
Paket 1 Dolžina	9,1 Cm
Paket 1 Teža	145 G
Embalažna enota Paketa 2	S03
Število enot v Paketu 2	24
Paket 2 Višina	30 Cm
Paket 2 Širina	30 Cm
Paket 2 Dolžina	40 Cm

Paket 2 Teža	3,68 Kg
Embalažna enota Paketa 3	PAL
Število enot v Paketu 3	192
Paket 3 Višina	60 Cm
Paket 3 Širina	80 Cm
Paket 3 Dolžina	70 Cm
Paket 3 Teža	35,84 Kg

Trajnost ponudbe

Status trajnostne ponudbe	Izdelek Green Premium
Uredba REACH	 Izjava REACH
Direktiva EU ROHS	Proaktivno zagotavljanje skladnosti (izdelek je zunaj področja uporabe direktive EU RoHS)
Brez živega srebra	Da
Uredba o RoHS za Kitajsko	 Izjava O RoHS Za Kitajsko
Informacije o izvzetju iz RoHS	 Da
Razkritje okoljskih podatkov	 Okoljski Profil Izdelka
Profil krožnega gospodarstva	 Informacije O Izteku Življenjske Dobe

Illuminated LED Unit

Dimensions

$\frac{\text{mm}}{\text{in.}}$




Modular Tower Lights Mounting



Drawing	Part number	Part name
A1	-	Top cover
-	Top cover (Silver)	
A2	XVUC9S	Buzzer unit
XVUC9SQ	Buzzer unit (Silver)	
A3	XVUC23	Green LED unit
XVUC24	Red LED unit	
XVUC25	Orange LED unit	
XVUC26	Blue LED unit	
XVUC27	White LED unit	
XVUC28	Yellow LED unit	
A4	XVUC29	Multi-LED unit
A5	XVUC29P	Multi-LED unit, Pulse signal
A6	XVUC9V	Sound unit
A7	XVUC9VP	Sound unit, Pulse signal
A8	XVUC020	Extender
XVUC020Q	Extender (Silver)	
A9	XVUC21B	DC body

Drawing	Part number	Part name
XVUC21BQ	DC body (Silver)	
A10	XVUC21M	AC body NPN
XVUC21MP	AC body PNP	
XVUC21MQP	AC body PNP (Silver)	
A11	XVUZ06	Flexible option
A12	XVUZ01	Fixing Unit - Direct mounting (3 pins)
XVUZ01Q	Fixing Unit - Direct mounting (Silver,3 pins)	
XVUZ03	Fixing Unit - Direct mounting (2 pins)	
XVUZ04	Fixing Unit - Direct mounting (4 pins)	
A13	XVUZ02	Fixing Unit - Plate with Pole (100 mm)
XVUZ02Q	Fixing Unit - Plate with Pole (100 mm, Silver)	
XVUZ400	Fixing Unit - Plate with Pole (400 mm)	
XVUZ800	Fixing Unit - Plate with Pole (800 mm)	
A14	XVUZ05	Fixing Unit - Plate with adjustment pole (100-385 mm)
A15	XVUC43	Green LED unit, Flash
XVUC44	Red LED unit, Flash	
XVUC45	Orange LED unit, Flash	
XVUC46	Blue LED unit, Flash	
XVUC47	White LED unit, Flash	
XVUC48	Yellow LED unit, Flash	
A16	XVUZ100T	Fixing Unit - Metal bracket with pole (100 mm)
XVUZ250T	Fixing Unit - Metal bracket with pole(250 mm)	
XVUZ400T	Fixing Unit - Metal bracket with pole (400 mm)	
A17	XVUZ12	Fixing plate for use on vertical support - black

Illuminated Units, Multi-LED and Audible Units Wiring

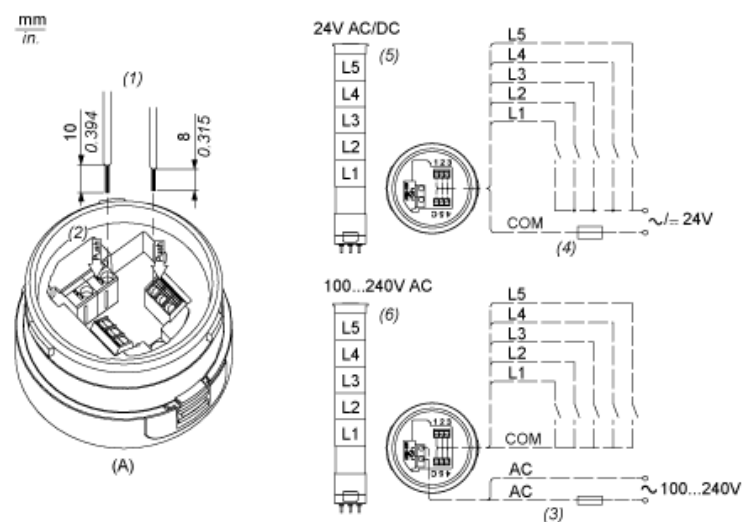

- (A) Fixing Unit
- (1) Dimensions of Wiring size
- (2) Push-in Wire Connectors
- (3) Fuse : 2A ,250V
- (4) Fuse : 0.5A ,125V
- (5) Modular Tower Lights 24V AC/DC
- (6) Modular Tower Lights 100...240V AC
- L1 to Illuminated LED Units
- L5 :