


Tehničke karakteristike proizvoda Karakteristike

NU821820 2x8mod nadgradna kutija bela antib

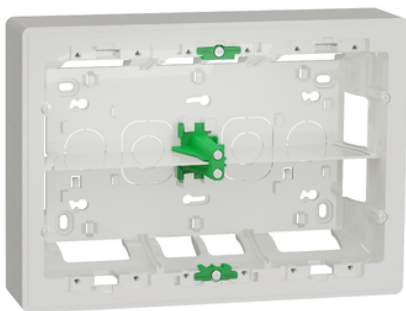

Osnovne informacije

Grupa proizvoda	New Unica
Primena uređaja	Montaža
Tip proizvoda ili komponente	Montažna kutija
Broj modula	2 x 8 modules
Način pričvršćivanja	Zavrtnjima

Dopunske informacije

Montaža uređaja	Nadgradno
Kablovski uvod	5 odvojive ploče 2 dno cable entries 30 mm 2 dno cable entries 20 mm 2 dno cable entries 25 mm
Materijal	ABS (akrilonitril-butadien-stiren): kutija ABS (akrilonitril-butadien-stiren): separator PC: tower
Obrada površine	Antibakterijska
Dubina	50 mm
Širina	230 mm
Visina	165 mm
Masa proizvoda	0,31 kg
Otpornost na hemijske supstance	Otporan na alkohol (70%) Otporan na alkohol (96%) Otporan na A-mlečnu kiselinu Otporan na razblaženi kvarterni amonijum Otporan na razblaženo izbeljivač Otporan na razblažen amonijak Otporan na vodu sa sapunom Otporan na čistač kristala Otporan na vodonik peroksid 10 zapremina Otporan na heksan

Okruženje

Ik stepen zaštite	IK04
-------------------	------

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8,000 cm
Package 1 Width	18,000 cm
Package 1 Length	25,000 cm
Package 1 Weight	424,000 g
Unit Type of Package 2	S04
Number of Units in Package 2	14

Package 2 Height	30,000 cm
Package 2 Width	40,000 cm
Package 2 Length	60,000 cm
Package 2 Weight	6,950 kg
Unit Type of Package 3	P06
Number of Units in Package 3	56
Package 3 Height	75,000 cm
Package 3 Width	60,000 cm
Package 3 Length	80,000 cm
Package 3 Weight	34,693 kg

Održivost ponude

Status održive ponude	Green Premium proizvod
Propis REACH	 REACH Deklaracija
REACH bez SVHC	Da
EU RoHS direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)
RoHS regulativa za Kinu	 RoHS Deklaracija Za Kinu
Informacije o RoHS izuzecima	 Da
Izjava o zaštiti okoliša	 Profil Ekološke Prihvatljivosti Proizvoda
Profil cirkularnosti	Nema potrebe za namenskim operacijama recikliranja