


Product data sheet

Characteristics

4515210

Performa - mesh tray - stainless steel - 70 mm
x 100 mm x 3000 mm

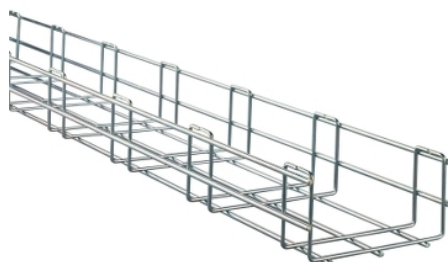

Main

Range of product	Performa
Product or component type	Mesh tray
Quantity per set	12 m

Complementary

Shape	U-shape
Material	Steel AISI 304 (stainless steel)
Atmospheric-corrosivity category	C5-I
Longitudinal wire diameter	3.9 mm
Transversal wire diameter	3.9 mm
Cable cross section	5268 mm ²
Standards	EN 50102 DIN 4102-12 IEC 61537 EN/ISO 9227 IEC 60068-2-75
Length	3 m
Height	75 mm
Width	100 mm
Height compatibility	70 mm
Width compatibility	100 mm
Surface treatment compatibility	Stainless steel

Environment

Ambient air temperature for operation	-40...120 °C
IK degree of protection	IK10

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8 cm
Package 1 Width	11.5 cm
Package 1 Length	300 cm
Package 1 Weight	7.92 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------