


Product data sheet

Characteristics

4515220

Performa - mesh tray - stainless steel - 70 mm
x 200 mm x 3000 mm

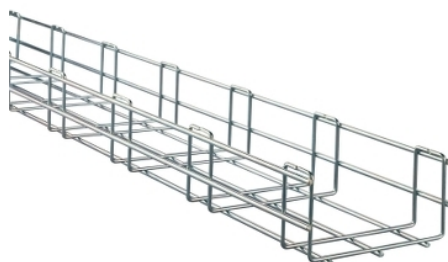

Main

Range of product	Performa
Product or component type	Mesh tray
Quantity per set	6 m

Complementary

Shape	U-shape
Material	Steel AISI 304 (stainless steel)
Atmospheric-corrosivity category	C5-I
Longitudinal wire diameter	3.9 mm
Transversal wire diameter	3.9 mm
Cable cross section	12328 mm ²
Standards	IEC 61537 IEC 60068-2-75 EN/ISO 9227 DIN 4102-12 EN 50102
Length	3 m
Height	75 mm
Width	200 mm
Height compatibility	70 mm
Width compatibility	200 mm
Surface treatment compatibility	Stainless steel

Environment

Ambient air temperature for operation	-40...120 °C
IK degree of protection	IK10

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8 cm
Package 1 Width	20.5 cm
Package 1 Length	300 cm
Package 1 Weight	1.236 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations