


Product data sheet

Characteristics

CSU08542009

Stago - cover internal rising piece formed 120mm pre-galvanized

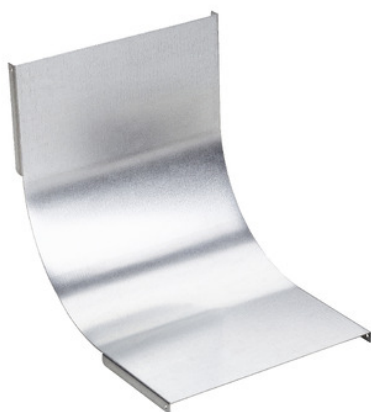

Main

Range	Stago
Product or component type	Cover
Mounting location	Partly outdoor environment with low exposure to corrosion ware-houses and parking garages

Complementary

Operating angle	90 °
Direction change type	Vertical
Product destination	Rising piece KG281 for cable tray 35 mm 120 mm width Rising piece KG281 for cable tray 60 mm 120 mm width Rising piece KG281 for cable tray 85 mm 120 mm width Rising piece KG281 for cable tray 110 mm 120 mm width
Fixing mode	Screwless
Material with surface treatment	Steel pre-galvanized
Corrosion class	C2
Length	219 mm
Height	125 mm
Width	219 mm
Net weight	0.402 kg / set of 1

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations