


Product data sheet

Characteristics

NSYEC68

Plain cable gland plate, PanelSeT SFN,
Spacial SF, for electrical enclosure W600
D800mm, fixed by clips

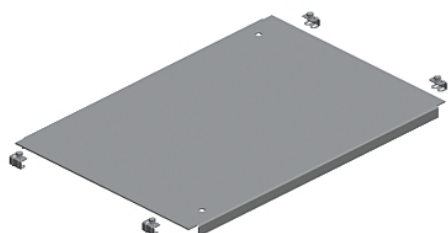

Main

Range	Spacial
Product or component type	Cable gland plate
Accessory / separate part category	Cable management accessory
Application	Multi-purpose Electronic application
Range compatibility	Spacial Spacial SF
Mounting location	Enclosure bottom
Cable gland type	Standard
Cable entry	Plain
Device composition	Fixing elements 1 plate
Quantity per set	Set of 1
Material	Galvanised steel

Complementary

Height	30 mm
Width	Nominal: 600 mm Useful: 416 mm
Depth	800 Mm nominal: 710 mm real:
Thickness	1.5 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.79 cm
Package 1 Width	45.47 cm
Package 1 Length	71.63 cm
Package 1 Weight	4.27 kg
Unit Type of Package 2	PAM
Number of Units in Package 2	40
Package 2 Height	65 cm
Package 2 Width	100 cm
Package 2 Length	120 cm
Package 2 Weight	179 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------