


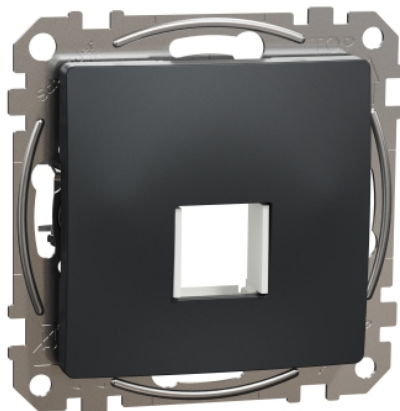

Main

Range name	Sedna Design & Elements
Range	Sedna
Device application	Mounting
Function	Central plate
Delivery form	Cover plate with fixing frame
Product destination	Universal keystone connector
Socket number	1
Colour tint	Anthracite (RAL 7021)
Device mounting	Flush

Complementary

Surface treatment	Painted
Fixing mode	Claws, span of claws working range: 51...80 mm Screws
Height	73 mm
Width	73 mm
Depth	35 mm
Net weight	0.038 kg
Material	Thermoplastic ABS-UV stabilised
Surface finish	Matt
IK degree of protection	IK02
Connector type	RJ45 RJ11 HDMI VGA

Environment

IP degree of protection	IP20
-------------------------	------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.000 cm
Package 1 Width	8.000 cm
Package 1 Length	8.000 cm
Package 1 Weight	48.000 g
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	9.500 cm
Package 2 Width	18.500 cm
Package 2 Length	27.500 cm
Package 2 Weight	566.000 g
Unit Type of Package 3	S04
Number of Units in Package 3	120
Package 3 Height	30.000 cm

Package 3 Width	40.000 cm
Package 3 Length	60.000 cm
Package 3 Weight	7.439 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
Sustainable packaging	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations