


XUSZSC138R

Telemecanique Safety light curtains XUSL,
Column without mirror 1200 mm with cable
gland PG11, Hp = 1060 mm

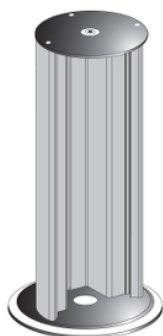

Main

Range of product	Telemecanique Safety light curtains XUSL
Accessory / separate part category	Mounting and fixing accessories
Accessory / separate part type	Fixing column
Offer type	Without mirror
Product compatibility	XUSL.E...76 to XUSL.E...106 with 4 beams XUSL.E...76 to XUSL.E...106 with 3 beams
Accessory / separate part destination	Safety light curtain type 4 Safety light curtain type 2

Complementary

Ambient air temperature for operation	-30...55 °C -30...55 °C
Ambient air temperature for storage	-30...70 °C -30...70 °C
Kit composition	1 x cable gland(s), Pg 11
Column height	1330 mm
Height protected	1060 mm
Net weight	4.5 kg

Packing Units


Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	14.0 cm
Package 1 Width	20.0 cm
Package 1 Length	142.0 cm
Package 1 Weight	6.2 kg

Offer Sustainability


Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
California proposition 65	WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Dimensions

 With XUSZFB2



With XUSZFB1

 

Mounting and Clearance

