


XZCE13P124M

Adaptor, plastic, tapped hole Pg 13.5, for male connector, M12, 4 wire

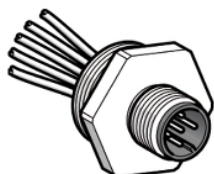

Main

Accessory / separate part designation	4-wire connector adaptor
Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector adaptor
Cable composition	4 x 0.34 mm ²
Thread type	Pg 13.5
[In] rated current	4 A

Complementary

Cable length	100 mm
Total number of wires	4
Electrical connection	1 male connector M12 5 straight
Cable connector fixing	Screw-on
Body material	Plastic
Insulation resistance	> 1000000000 Ohm
Maximum resistance across terminals	5000 mOhm
[Ue] rated operational voltage	250 V AC 300 V DC
Net weight	0.02 kg

Environment

IP degree of protection	IP67
Ambient air temperature for operation	-25...80 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.500 cm
Package 1 Width	10.000 cm
Package 1 Length	7.500 cm
Package 1 Weight	9.800 g
Unit Type of Package 2	BB1
Number of Units in Package 2	100
Package 2 Height	7.500 cm
Package 2 Width	28.000 cm
Package 2 Length	38.000 cm
Package 2 Weight	983.000 g
Unit Type of Package 3	S02
Number of Units in Package 3	200
Package 3 Height	15 cm
Package 3 Width	30 cm
Package 3 Length	40 cm
Package 3 Weight	2.451 kg


Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
For all Reach Rohs enquiries contact us at	sustainability@tesensors.com

Contractual warranty

Warranty	18 months
----------	-----------


Dimensions

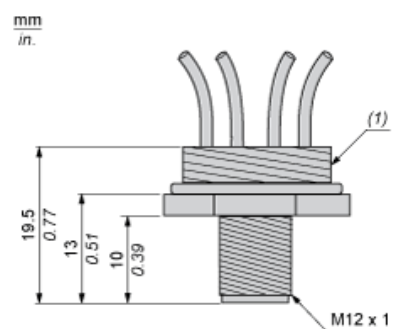

(1) Pg 13.5 cable gland

Connections and Schemes

Connector

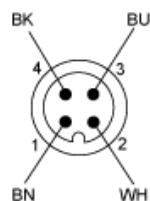

BN : Brown
BK : Black
BU : Blue
WH : White