



## Main

|                                    |                                  |
|------------------------------------|----------------------------------|
| Range of product                   | Telemecanique Cabling components |
| Accessory / separate part category | Cabling accessory                |
| Accessory / separate part type     | Pre-wired connectors             |
| Series name                        | Application                      |

## Complementary

|                                |                                       |
|--------------------------------|---------------------------------------|
| Electrical connection          | Straight female connector M12, 4 pins |
| Cable connector fixing         | Screw-on                              |
| Collar material                | Stainless steel 316L                  |
| Status LED                     | Without                               |
| Cable length                   | 5 m                                   |
| Cable outer diameter           | 5.3 mm                                |
| Cable composition              | 4 x 0.34 mm <sup>2</sup>              |
| Wire insulation material       | PVC                                   |
| [Ue] rated operational voltage | 250 V AC<br>300 V DC                  |
| [In] rated current             | 4 A                                   |
| Contact resistance             | 5000 µOhm                             |
| Minimum insulating resistance  | 1 GΩ                                  |
| Net weight                     | 0.19 kg                               |

## Environment

|                                       |                    |
|---------------------------------------|--------------------|
| IP degree of protection               | IP69K              |
| Ambient air temperature for operation | -25...85 °C static |
| Ambient air temperature for storage   | -35...100 °C       |

## Packing Units

|                              |           |
|------------------------------|-----------|
| Unit Type of Package 1       | PCE       |
| Number of Units in Package 1 | 1         |
| Package 1 Height             | 3.000 cm  |
| Package 1 Width              | 18.000 cm |
| Package 1 Length             | 18.000 cm |
| Package 1 Weight             | 154.000 g |
| Unit Type of Package 2       | S02       |
| Number of Units in Package 2 | 20        |
| Package 2 Height             | 15.000 cm |
| Package 2 Width              | 30.000 cm |
| Package 2 Length             | 40.000 cm |
| Package 2 Weight             | 3.389 kg  |


## Offer Sustainability

|                                            |                                                                                                                                                                                                                                                                                                                                                                                   |
|--------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Toxic heavy metal free                     | Yes                                                                                                                                                                                                                                                                                                                                                                               |
| California proposition 65                  | WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a> |
| For all Reach Rohs enquiries contact us at | <a href="mailto:sustainability@tesensors.com">sustainability@tesensors.com</a>                                                                                                                                                                                                                                                                                                    |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

## Dimensions

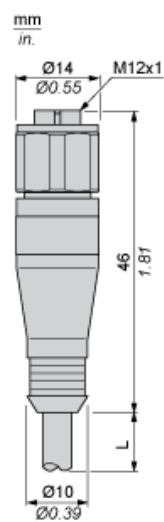

L : Length of cable

---

## Connections and Schemes

---

### Connector



BN : Brown  
BK : Black  
BU : Blue  
WH : White